

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0513820500

Status:


Active

Overview:

MicroClasp™ Wire-to-Board System

Description:

2.00mm Pitch MicroClasp™ Wire-to-Board Receptacle Housing, Positive Lock, Single Row, 5 circuits

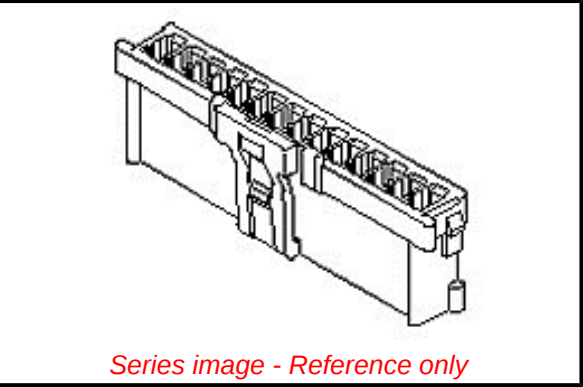

Documents:

3D Model

Packaging Specification 513829200 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-51382-004 (PDF)

General	
Product Family	Crimp Housings
Series	51382
Application	Signal, Wire-to-Board
Overview	MicroClasp™ Wire-to-Board System
Product Name	MicroClasp™
UPC	800756632278
Physical	
Circuits (maximum)	5
Color - Resin	White
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	294.800/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-25°C to +85°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	513829200
Product Specification	PS-51382-004, RPS-51382-006, RPS-51382-007, RPS-51382-008, RPS-51382-009, RPS-51382-010, RPS-51382-011, RPS-51382-012, RPS-51382-013, RPS-51382-014, RPS-51382-015, RPS-51382-018
Sales Drawing	SD-51382-002

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

51382 Series

Mates With

55932 Vertical Header, 55935 Right Angle Header

Use With

56134 Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION