

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1062835203](#)
Status: **Active**
Overview: [QSFP+ Interconnect Solution](#)
Description: Quad Small Form-factor Pluggable Plus (QSFP+) Optical Breakout Cable Assembly, 4 TX, 4 RX; 8 Fiber MTP* - 8LC Multimode 50/125µm 3mm Round Cable Plenum, Standard Bandwidth (OM2), 5.0m (16.40') Length, Aqua Cable

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Fiber Optic Assemblies
Series	106283
Boot Type	N/A
Connector to Connector	MTP*-to-LC
Mode	Multimode Enhanced
Overview	QSFP+ Interconnect Solution
Product Name	iPass+™ HD, MPO, QSFP+
UPC	800756704005

Physical


Cable Length	5.0m
Cable Size	50/125µm
Fiber (Core/Cladding)	50/125µm
Net Weight	82.700/g
Single Ended	No
Wire/Cable Type	Round

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-106283-5YYY
---------------	----------------

*MTP is a registered trademark of US Conec Ltd.

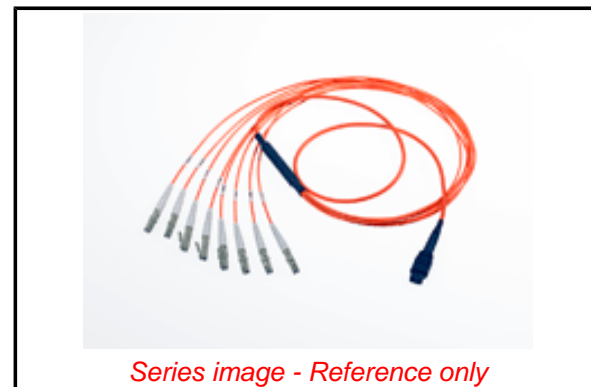

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/79/2015 (17 December 2015) 2,4-Di-tert-butyl-6-(5-chlorobenzotriazol-2-yl)p

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

Search Parts in this Series

[106283](#) Series