

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300060250](#)
Status: **Active**
Overview: [Brad® Mini-Change® Connectors](#)
Description: Mini-Change® A-Size Single-Ended Cordset, 3 Poles, Female (Straight) to Pigtail, 16 AWG, PVC Cable, 9.14m (30.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E152210

General

Product Family Industrial Cordsets
 Series [130006](#)
 Connector End A Mini-Change®
 Connector End B Pigtail
 IP Rating IP67
 Overview [Brad® Mini-Change® Connectors](#)
 Product Name Mini-Change®
 Protocol N/A
 Region America
 Type Single Ended
 UPC 78678843016

Physical

Cable Diameter 10.41mm (.410")
 Cable Length 9.14m (30.0')
 Color - Cable Jacket Yellow
 Coupling Style Threaded
 Gender Female-Pigtail
 Keyway Single
 LED Indicator No
 Material - Cable Jacket PVC
 Material - Connector Body PVC
 Material - Contact Copper Alloy
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold
 Orientation Straight
 Poles 3
 Temperature Range - Operating -20°C to +105°C
 Wire Size AWG 16
 Wire/Cable Type ST00W

Electrical


Current - Maximum per Contact 13.0A
 Voltage - Maximum 600V

Material Info

Old Part Number 103000A01F300

Reference - Drawing Numbers

Sales Drawing SD-130006-008

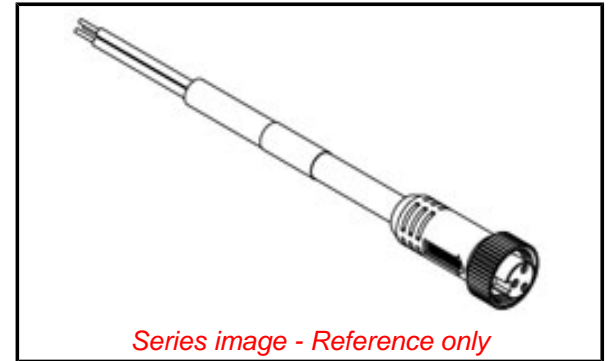

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/108/2014 (17 Dec 2014)

Bis (2-ethylhexyl) phthalate (DEHP)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

Search Parts in this Series

[130006 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION