

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1720630312](#)
Status: **Active**
Overview: [Mega-Fit® Power Connectors](#)
Description: Mega-Fit® Female Crimp Terminal, 12 AWG 15µ" Gold (Au) Plating, Reel

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-76823-001 \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	172063
Application	Power
Crimp Quality Equipment	Yes
Overview	Mega-Fit® Power Connectors
Product Name	Mega-Fit®
UPC	887191474595

Physical

Gender	Female
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Nickel
Net Weight	0.340/g
Packaging Type	Reel
Plating min - Mating	0.381µm
Plating min - Termination	1.270µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.35mm (0.171")
Wire Size AWG	12
Wire Size mm²	N/A

Electrical

Current - Maximum per Contact	23.0A
Voltage - Maximum	600V


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-76823-001
Sales Drawing	SD-76823-0100

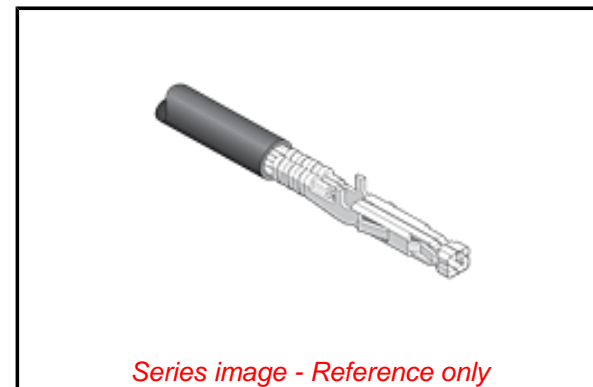

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

[172063](#) Series

Use With

Mega-Fit® Crimp Housing [171692](#) , [170001](#)