

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200845108](#)
Status: **Active**
Overview: [Brad® Ultra-Lock® Connection System](#)
Description: Ultra-Lock® (M12) Receptacle, 4 Poles, M16x1.5 Mounting Threads, Male (Straight) to 0.34mm² PVC Leads, 0.30m (11.81") Length

Documents:
[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Receptacles
Series	120084
IP Rating	IP69K
NEMA Rating	NEMA 6
Overview	Brad® Ultra-Lock® Connection System
Product Name	Ultra-Lock® (M12)
Type	Single Ended (pigtail)
UPC	883906778910

Physical

Coupling Type	External Thread
Gender	Male
Keyway	Single
Length	0.30m
Material - Component	Nickel-plated Brass
Mounting Thread Size	M16 x 1.5
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	22
Wire/Cable Type	Leads, UL 1061

Electrical


Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC

Material Info

Old Part Number	WR4U26E03C3003
-----------------	----------------

Reference - Drawing Numbers

Sales Drawing	SD-120084-025
---------------	---------------

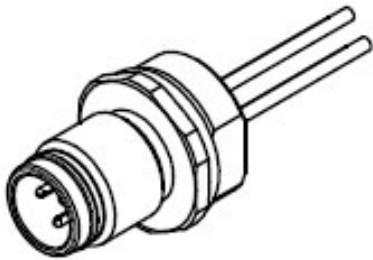

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant/Exempted

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS
ELV

China RoHS

50 Image
Not Relevant

Search Parts in this Series

[120084](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION