

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300680019](#)
Status: **Active**
Overview: Brad® Quick-Change® Connectors
Description: Quick-Change® AC Male to Micro-Change® Female Pass Thru, 4 Pole

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E258922

General

Product Family Field Attachable / Accessories
 Series [130068](#)
 IP Rating IP67
 Overview [Brad® Quick-Change® Connectors](#)
 Product Name Quick-Change®
 Type Gender Changer
 UPC 78678855020

Physical

Cable Diameter N/A
 Coupling Type Internal Thread
 Diagnostics / LEDs No
 Diagnostics Port No
 Gender Male-Female
 Keyway Single
 Material - Connector Body PVC
 Material - Contact Copper
 Material - Coupling Nut Black Epoxy Coated Zinc
 Material - Plating Mating Gold over Copper
 Orientation Straight
 Poles 4
 Temperature Range - Operating -20°C to +90°C
 Wire Size AWG N/A

Electrical


Current - Maximum per Contact 15.0A
 Voltage - Maximum 600V DC

Material Info

Old Part Number 1C4030-001

Reference - Drawing Numbers

Sales Drawing SD-130068-003

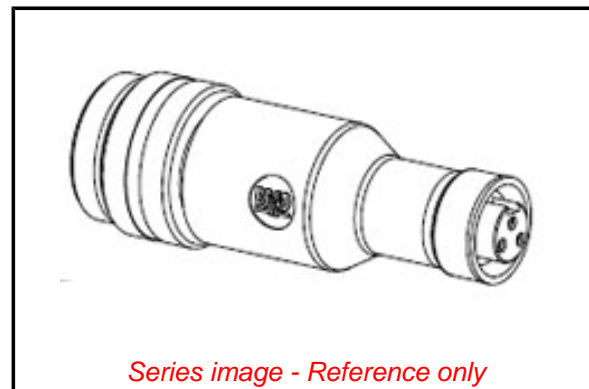

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Relevant

Search Parts in this Series

[130068](#) Series