

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0194340003](#)
Status: **Active**
Overview: MX150L™ Industrial Sealed Connector System
Description: MX150L™ Female Terminal for 10-12 AWG Wire

Documents:

Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification PK-19434-001 (PDF)	Product Literature (PDF)

Agency Certification

CSA	LR18689
UL	E152602

General

Product Family	Crimp Terminals
Series	19434
Application	Power
Comments	UL E152602
Crimp Quality Equipment	Yes
Overview	MX150L™ Industrial Sealed Connector System
Packaging Alternative	19434-0001 (Reel)
Product Literature Order No	987650-2181
Product Name	MX150L™
UPC	822350193153


Physical

Gender	Female
Material - Metal	Copper
Material - Plating Mating	Tin
Net Weight	0.844/g
Packaging Type	Bag
Wire Insulation Diameter	3.94mm-4.45mm
Wire Size AWG	10, 12
Wire Size mm ²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-19434-001
Sales Drawing	SD-19434-001

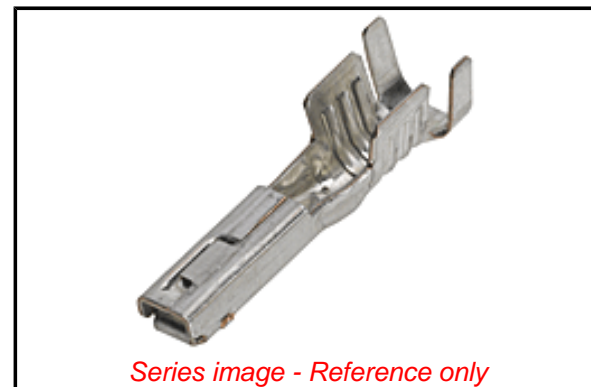

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

[19434 Series](#)

Mates With

[19431 Male Terminal](#)

Use With

[19432 Female Receptacle](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Hand Crimp Tool for	0638115300
Crimp Terminals	

This document was generated on 07/18/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION