


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301990025](#)  
**Status:** **Active**  
**Overview:** MAX-LOC® Plus Shielded Cord Grip Assemblies  
**Description:** Woodhead® MAX-LOC® Plus Shielded Cord-Grip Assembly, 2/0 AWG Cable with Black HNBR O-Ring and Grommet

**Documents:**

<a href="#">3D Model</a>	<a href="#">Packaging Specification PK-130199-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-130199-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>
<a href="#">Application Specification AS-130199-001 (PDF)</a>	

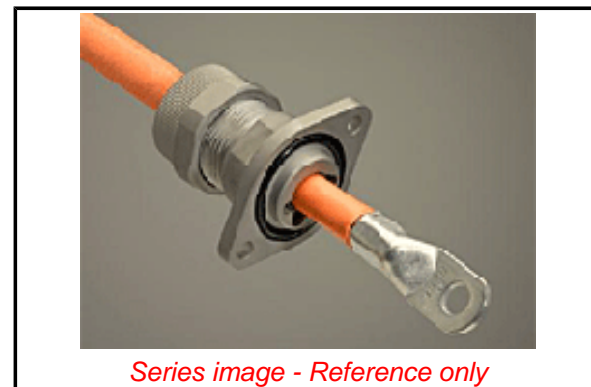

*Series image - Reference only*

**General**

Product Family	Cable Grips
Series	130199
Eye Type	N/A
O-Ring	Yes
Overview	MAX-LOC® Plus Shielded Cord Grip Assemblies
Product Literature Order No	987650-7321
Product Name	MAX-LOC®
Type	MAX-LOC® Connector
UPC	884982795129
Woodhead	Yes

**Physical**

Approximate Break Strength	N/A
Bale Length	N/A
Body Style	Straight
Cable Diameter	14.27-17.45mm (.562-.687")
Color - Grommet	Black
Gender	Female
Material - Body	Aluminum
Material - Grip	N/A
Mesh Length	N/A
Number of Holes	N/A
Thread Size	N/A

**Material Info**

**Reference - Drawing Numbers**

Application Specification	AS-130199-001
Packaging Specification	PK-130199-001
Product Specification	PS-130199-001
Sales Drawing	SD-130199-001

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ED/108/2014 (17 Dec  
2014)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any  
non-product compliance questions.

China ROHS  
ELV

Green Image  
Not Relevant

**Search Parts in this Series**  
[130199 Series](#)