

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 1300340006
Status: Active
Overview: Brad® Mini-Change® Connectors
Description: Mini-Change® Trunk Connector, Threaded, Single Keyway, Straight Male, 5 Poles

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR6837


General
Product Family Field Attachable / Accessories
Series 130034
IP Rating IP67
Overview Brad® Mini-Change® Connectors
Product Name Mini-Change®
Type Field Attachable Connector
UPC 78678848868

Physical
Cable Diameter N/A
Coupling Type External Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender Male
Keyway Single
Material - Connector Body Polyamide
Material - Contact Copper
Material - Coupling Nut Nickel-plated Brass
Material - Plating Mating n/a
Orientation Straight
Poles 5
Temperature Range - Operating -25°C to +90°C
Wire Size AWG N/A

Electrical
Current - Maximum per Contact 4.0A
Voltage - Maximum 36V

Material Info
Old Part Number 1A5006-34DN

Reference - Drawing Numbers
Sales Drawing SD-130034-002

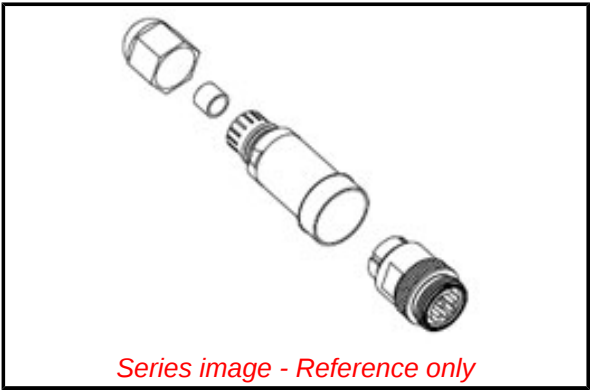

EU ELV
Not Relevant

EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
--	-------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant

Search Parts in this Series
130034 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION