

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010043](#)
Status: **Active**
Overview: [GWconnect® Heavy Duty Connectors \(HDC\)](#)
Description: [GWconnect® Turned Crimp Contact for 10A Inserts and Modules, Female, Silver \(Ag\) Plated Copper Alloy, 0.75mm² \(18 AWG\), 100 per Bag](#)

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|------------------|--|
| Product Family | Industrial Connectors / Enclosures |
| Series | 93601 |
| Contact Type | Turned Crimp Contact |
| Mates With | 93601 Male Turned Crimp Contact |
| Overview | GWconnect® Heavy Duty Connectors (HDC) |
| Product Category | Contacts |
| Product Name | GWconnect® |
| UPC | 887191866710 |
| Use With | S-D, S-DD, S-K, S-Q, S-QD, and S-M Inserts |

Physical

| | |
|--------------------|--------------|
| Gender | Female |
| Material - Contact | Copper Alloy |
| Material - Plating | Silver |
| Number of Grooves | 0 |
| Packaging Type | Bag |
| Stripping Length | 8.00mm |
| Wire Size AWG | 18 |
| Wire Size mm² | 0.75 |


Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 10.0A |
|-------------------------------|-------|

Material Info

| | |
|-----------------|-------------|
| Old Part Number | 7100.4203.0 |
|-----------------|-------------|

GWconnect® is a registered trademark of Molex Incorporated in Italy and may be registered in other jurisdictions.

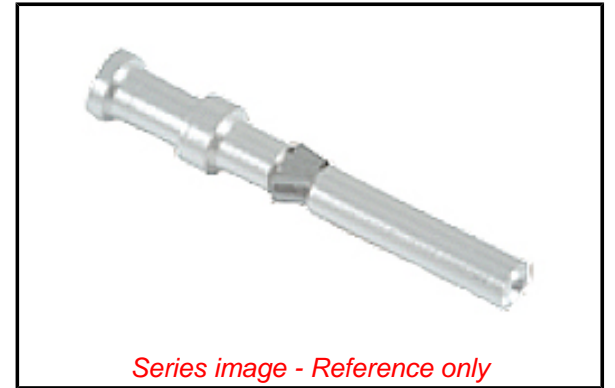

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

Search Parts in this Series

[93601](#) Series