

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0731000131

Status:


Active

Overview:

BNC RF Connectors

Description:

50 Ohms, BNC Right-Angle PCB Bulkhead Jack Receptacle with Board Locks, White PBT Housing, Nut and Lock Washer not included, One Piece Per Bag

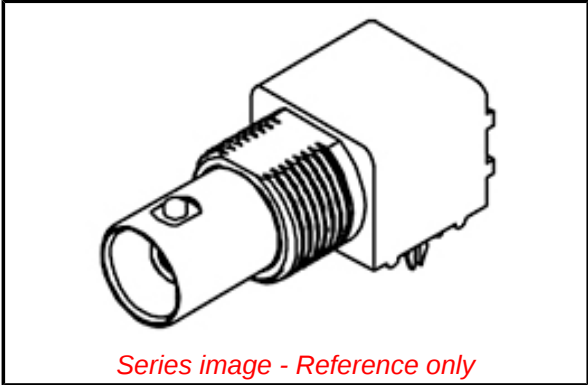

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	RF/Coax Connectors
Series	73100
Overview	BNC RF Connectors
Product Name	BNC
Style	PCB
UPC	800753686434
Wire/Cable Type	N/A
Physical	
Gender	Jack
Keying to Mating Part	None
Net Weight	9.865/g
Orientation	Right Angle
PCB Mounting	Through Hole
PCB Thickness - Recommended	3.20mm
Packaging Type	Bag
Panel Mount	Yes
Panel Mount Method	Bulkhead
Reverse Polar	No
Electrical	
Impedance	50#
Solder Process Data	
Lead-freeProcess Capability	WAVE
Process Temperature max. C	245
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-73100-0131

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

73100 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION