

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200720108

Status:


Active

Overview:

Brad® Micro-Change® (M12) Connectors

Description:

Micro-Change® (1/2"-20 UNF) Single-Ended Cordset, 2 Poles, Male (Straight) to Pigtail, 22 AWG, PVC Cable, 1.83m (6.0') Length

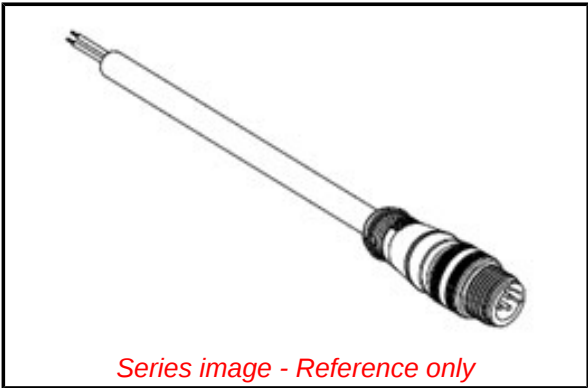

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Cordsets
Series	120072
Connector End A	Micro-Change® (1/2" - 20 UNF)
Connector End B	Pigtail
IP Rating	IP67
Overview	Brad® Micro-Change® (M12) Connectors
Product Name	Micro-Change® (1/2" - 20 UNF)
Protocol	N/A
Region	America
Type	Single Ended
UPC	78678833860
Physical	
Cable Diameter	5.72mm (.225")
Cable Length	1.83m (6.0')
Color - Cable Jacket	Yellow
Coupling Style	Threaded
Gender	Male-Pigtail
Keyway	Dual
LED Indicator	No
Material - Cable Jacket	PVC
Material - Connector Body	PVC
Material - Contact	Copper Alloy
Material - Coupling Nut	Black Epoxy Coated Zinc
Material - O-Ring	Nitrile Rubber
Material - Plating Mating	Gold over Nickel
Orientation	Straight
Poles	2
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	22
Wire/Cable Type	UL 2661
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Old Part Number	702006D02F060
Reference - Drawing Numbers	
Sales Drawing	SD-120072-014

EU ELV

Not Reviewed

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

Search Parts in this Series

120072 Series

This document was generated on 07/05/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION