

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0347960202](#)
Status: **Active**
Overview: [MX150™ Unsealed Connector System](#)
Description: MX150™ Cable Unsealed Female Connector, Single Row, 2 Circuits, Polarization B, Natural

Documents:

[3D Model](#) [Packaging Specification PK-31301-695 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Housings
Series	34796
Application	Power, Wire-to-Wire
Overview	MX150™ Unsealed Connector System
Polarization	B
Product Name	MX150™ Unsealed
UPC	884982969469

Physical

Circuits (maximum)	2
Color - Resin	Natural
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	2.010/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.50mm
Pitch - Termination Interface	3.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Electrical

Current - Maximum per Contact	22.0A
-------------------------------	-------


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-31301-695
Sales Drawing	SD-34796-001

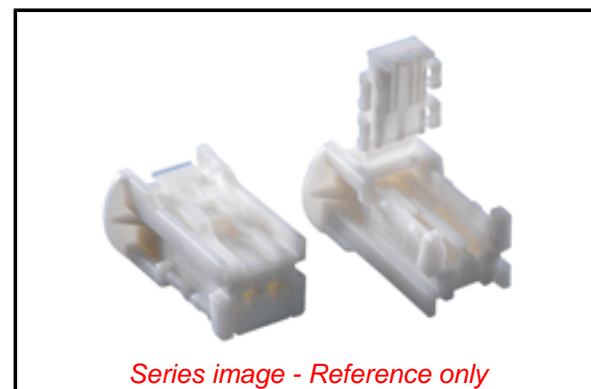

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Not Relevant

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

China RoHS

Not Relevant

Compliant

Search Parts in this Series

[34796 Series](#)

Mates With

[34797 3.50mm Pitch MX150™ Cable Unsealed Male](#)

Use With

MX150™ Female Terminal [33012-2021](#) , [33012-2022](#) , [33012-2023](#) , [33012-3021](#) , [33012-3022](#) , [33012-3023](#)