

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1302990400

Status:

Active

Overview:

Brad® Micro-Change® (M12) Connectors

Description:

Brad® Micro-Change® (M12) Harsh-Duty Receptacle, 5 Pole, A-Code, Straight

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Packaging Specification PK-130299-001 (PDF)

General

Product Family

Industrial Receptacles

Series

130299

IP Rating

IP67

Overview

Brad® Micro-Change® (M12) Connectors

Product Name

Micro-Change® (M12)

Type

PCB Mount

UPC

78172513055

Physical

Coupling Type

Internal Thread

Gender

Female

Keyway

A-coded

Length

N/A

Material - Component

Nickel-plated Zinc Die-Cast

Mounting Thread Size

M12 x 1.0

Orientation

Straight

Panel Mount

Back, Front

Poles

5

Temperature Range - Operating

-40°C to +85°C

Wire Size AWG

N/A

Wire/Cable Type

N/A

Electrical

Current - Maximum per Contact

4.0A

Voltage - Maximum

250V AC/DC

Material Info


Reference - Drawing Numbers

Packaging Specification

PK-130299-001

Sales Drawing

SD-130299-008

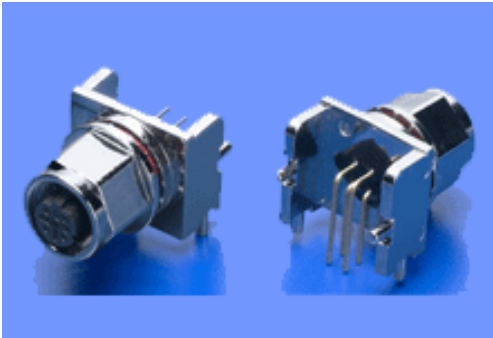

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

Search Parts in this Series

130299 Series

Mates With

Male A-Code Cable Assembly

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION