

Brand New! Unique Product Development!

Medium-Power Thru Panel Terminal Block

Pitch: 11mm

300 Volts / 25 Amps

PART#:

OGM-300NE

Type:

Medium Power Thru Panel

Features:

Thru-Panel Barrier

Applications:

Suitable for:
 Motor Controls
 Electric Heaters
 Industrial Controls
 Pumps
 Power Supplies
 Lighting

Electrical

Rated Voltage:

300V

Rated Current:

25A

Wire Size:

14-22 AWG

Operating Temperature:

-40C to +90C

Materials

Housing:

Polycarbonate (UL94V-0)
 Standard Color: Black

Cover:

Polycarbonate (UL94V-0), Clear

Terminal:

Brass, Nickel Plated

Positions Available:

2-23

Screw Size:


M4, Brass, Nickel plated

Withstanding Voltage:

AC2000V

Torque:

1.2 inch lbs.

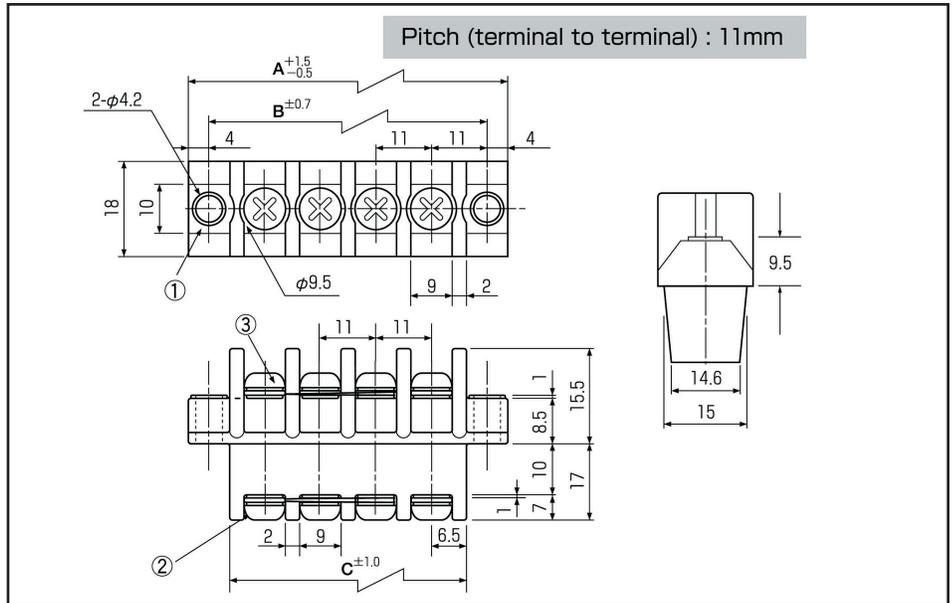

BlockMaster Electronics' new OGM-300NE Series are medium power, thru-panel terminal blocks available in 2-23 positions.

BlockMaster's OGM-300NE series are perfect for interfacing internally wired products to the outside world. Each terminal has a screw with lockwasher for convenient field wiring as shown. Suitable for motor controls, electric heaters, industrial controls or any medium power field wiring to control box application.



HOW TO ORDER:

OGM-300NE **P**

↓
Poles
 2-23



1400 Howard Street Phone: (847) 956-1680
 Elk Grove Village, IL 60007 Fax: (847) 956-1690

www.BlockMaster.com