


8U Desktop Rack - 2-Post Open Frame Rack

Product ID: RK80D

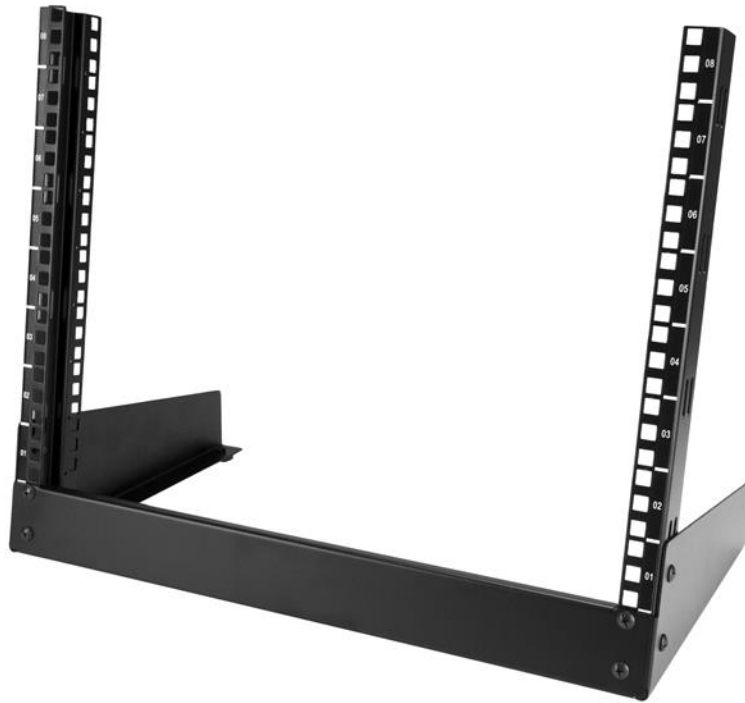

This 2-post desktop rack provides 8U of storage space for mounting smaller A/V and IT equipment.

Save money with a low-cost mounting solution

With this 2-post rack, you can mount equipment at a fraction of the cost of conventional racks. The lightweight rack is engineered to meet EIA-310 rack-mount standards and is constructed of solid steel, ensuring a sturdy and safe mounting solution for your mission-critical equipment.

Improve efficiency and accessibility in your office or server room

The rack features an open frame, free standing design that saves space with a small footprint. It gives you the ability to place rack-mount equipment on any surface in your office, such as your desk. This makes it easy to access your equipment on a daily basis.

Hassle-free setup

The 2-post rack is easy to assemble and includes a pack of 20 M5 screws and cage nuts.

If you're looking for a desktop mounting solution with more rack units, StarTech.com also offers a [12U 2-post desktop rack](#).

The RK80D is backed by a StarTech.com lifetime warranty and free technical support.

Certifications, Reports and Compatibility



Applications

- Place KVMs and rack-mount computers or server systems neatly on or beside your desk
- Save space in your SoHo (small office, home office) or server room, by placing equipment on desk or other surface, instead of taking up floor space

Features

- Save money with a rack-mount solution that's a fraction of the cost of conventional racks
- Improve efficiency in your office or server room by placing equipment on your desk
- Easy setup with hassle-free assembly and mounting hardware included
- Includes 20 M5 screws and cage nuts
- Lightweight design
- EIA-310 compliant

Hardware	Warranty	Lifetime
	Fan(s)	No
	Frame Type	Open Frame
	Front Door Type	Open
	Industry Standards	EIA RS310-C
	Rack Type	2-Post
	U Height	8U
	Wallmountable	No
Performance	Weight Capacity	110.5 lb [50 kg]
Physical Characteristics	Color	Black
	Enclosure Type	Steel
	Product Height	16.3 in [415 mm]
	Product Length	11.7 in [298 mm]
	Product Weight	6.9 lb [3.1 kg]
	Product Width	19.8 in [503 mm]
Packaging Information	Shipping (Package) Weight	5.7 lb [2.6 kg]
What's in the Box	Included in Package	1 - left base bracket
		1 - right base bracket
		1 - left vertical rail
		1 - right vertical rail
		1 - front base bracket
		4 - rubber feet
		8 - assembly screws
		20 - M5 screws
		20 - M5 cage nuts
		1 - instruction manual

Product appearance and specifications are subject to change without notice.