

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [\*\*1301530019\*\*](#)  
**Status:** **Active**  
**Overview:** Ground Fault Circuit Interrupter (GFCI) Products  
**Description:** Safeway® In-Line Commercial GFCI, Permanent Mount, Single Phase, Manual Reset, Molded NEMA 5-15, 15A, 120V, 0.61m (2.0') Cord Length

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

[Product Literature \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E66308

**General**

Product Family	Power Distribution
Series	<a href="#">130153</a>
Enclosure Rating	NEMA 4
GFCI Reset	Manual
Mounting Style	Portable
Open Neutral Relay	Yes
Overview	<a href="#">Ground Fault Circuit Interrupter (GFCI) Products</a>
Product Literature Order No	987650-7737, 987651-0452
Product Name	Safeway®
Receptacle Type	N/A
Type	GFCI Commercial Duty, Single Phase
UPC	78678828399
Woodhead	Yes

**Physical**


Cord Diameter	9.40mm (.370")
Cord Grip Body Size	Internal Double C-Clamp
Cord Length	0.61m (2.0')
Feed-Thru	Yes
Flip Lid	No
Material - Housing	Nylon
Net Weight	1015.592/g
Number of Receptacles	1
Packaging Type	Bag

**Electrical**

Cord Type	14/3 SJTW
Current - Maximum per Contact	15.0A
GFCI	Yes-In-line
Ground Continuity Monitor	No
NEMA Configuration	NEMA 5-15
Voltage - Maximum	120V AC

**Material Info**

Engineering Number	15050-1
--------------------	---------

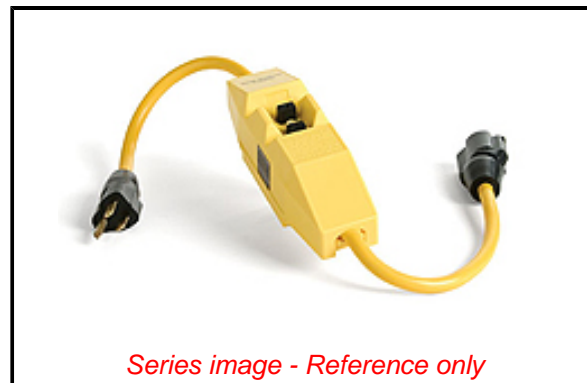

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

**Search Parts in this Series**

[130153 Series](#)