

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190080038](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: Flag Krimptite™ Quick Disconnect, Female, for 12-14 (3.30-2.00mm²) Wire, Box, Tab 6.35 x 0.81mm

Documents:

[Drawing \(PDF\)](#)
[Product Specification PS-19902-005-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Quick Disconnects
Series [19008](#)
Comments Fits Hermetic Tabs
Crimp Quality Equipment Yes
Insulated No
Overview [Standard Quick-Disconnect Terminals](#)
Product Name Krimptite™
Type Quick Disconnect
UPC 800755046762

Physical

Barrel Type Closed
Gender Female
Glow-Wire Compliant No
Insulation None
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.785/g
Orientation Flag
Packaging Type Bag
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating Per Wire Specification
Termination Interface: Style Crimp or Compression
Wire Size AWG 12, 14

Electrical

Voltage - Maximum Per Wire Specification

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Engineering Number B-175

Reference - Drawing Numbers

Product Specification PS-19902-005-001, PS-19902-011-001,
PS-19902-013-001
Sales Drawing SD-19008-009

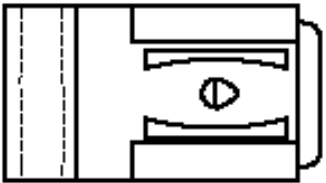

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series

[19008 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION