

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0190670082
Status: Active
Overview: Solderless Terminals
Description: NylaKrimp™ Funnel Entry Ring Tongue Terminal for 4 AWG Wire, Stud Size 1/4" (M6)

Documents:
3D Model Product Specification PS-19902-013-001 (PDF)
Drawing (PDF) Product Specification PS-19902-016-001 (PDF)
Product Specification PS-19902-011-001 (PDF) RoHS Certificate of Compliance (PDF)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19067
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name NylaKrimp™
Type Ring
UPC 800753066526

Physical
Barrel Type Closed - Brazed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 9.593/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 1/4" (M6)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 12.95mm max.
Wire Size AWG 4

Material Info
Engineering Number F-967-14

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001,
PS-19902-016-001
Sales Drawing SD-19067-018

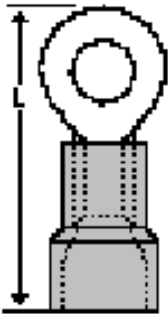

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/21/2016 (20 June
2016)
Halogen-Free
Status
Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
19067 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION