





Front panels

as filler panel, flat

Material:

2.5 mm aluminium, natural anodised.

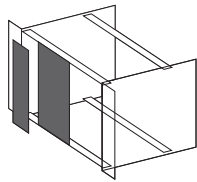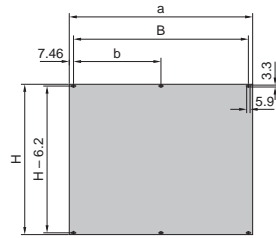

Also required:

Captive screws and plastic collars, packs of 100 set, Model No. RP 3658.160, see page 576.

HP	a mm	B mm	b mm	Model No. RP						
				1 U H = 39.8	2 U H = 84.25	3 U H = 128.7	4 U H = 173.15	6 U H = 262.05	7 U H = 306.5	9 U H = 395.4
2	9.8	-	-	-	-	3684.889	-	3684.911	-	3684.738
3	14.9	-	-	-	-	3684.890	-	3684.912	-	-
4	20.0	-	-	-	-	3684.891	-	3684.913	-	3684.739
5	25.1	-	-	-	-	3684.892	-	3684.914	-	-
6	30.1	-	-	-	-	3684.893	-	3684.915	-	-
7	35.2	-	-	-	-	3684.894	-	3684.916	-	-
8	40.3	-	-	-	-	3684.895	-	3684.917	-	3684.740
10	50.5	35.6	-	-	-	3684.896	-	3684.918	-	-
12	60.6	45.7	-	-	-	3684.897	-	3684.919	-	3684.741
14	70.8	55.9	-	-	-	3684.898	-	3684.920	-	-
20	101.3	86.4	-	-	-	3684.899	-	3684.921	-	-
21	106.4	91.4	-	-	-	3685.350	3684.900	3684.922	-	-
24	121.7	106.7	-	-	-	3685.429	-	-	-	-
27	136.8	121.9	-	-	-	-	3684.901	-	3684.923	-
28	141.9	127.0	-	-	-	-	3684.902	-	3684.924	-
40	202.9	188.0	-	-	-	-	3684.903	-	3684.976	-
42	213.0	198.1	-	-	-	3684.885	3684.887	3684.904	3684.908	3684.925
60	304.5	289.6	-	-	-	-	3684.905	-	-	-
63	319.7	304.8	152.4	-	-	-	3684.906	3684.909	3684.926	3684.929
84	426.4	411.5	203.2	3684.886	3684.888	3684.907	3684.910	3684.927	3684.930	3684.743
85	413.5	411.5	203.2	-	-	3684.744	3684.745	3684.746	3684.747	3684.748