

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0887418700

Status:


Active

Overview:

MicroCross™ DVI Connectors and Cable Assemblies

Description:

MicroCross™ DVI Digital Visual Interface, Shielded I/O Adapter, DVI-Analog Plug-VGA Receptacle

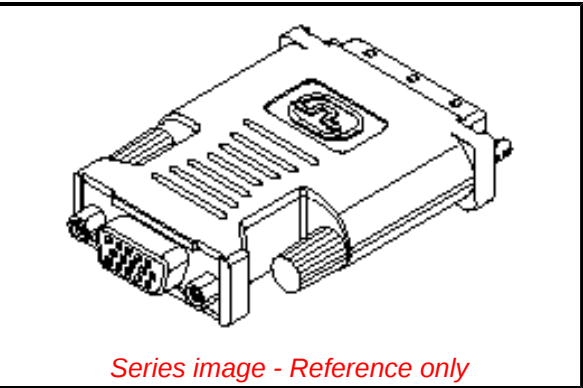

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	I/O Connectors
Series	88744
Application	Wire-to-Board
Comments	DVI-Analog Plug-VGA Receptacle
Component Type	Adapter
Obsolete Date	2003/01/01
Overview	MicroCross™ DVI Connectors and Cable Assemblies
Product Name	MicroCross™ DVI
Type	N/A
UPC	800754018982
Physical	
Circuits (Loaded)	29
Circuits (maximum)	29
Color - Resin	Black
Durability (mating cycles max)	100
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	33.220/g
Orientation	Vertical
PCB Retention	Yes
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.90mm, 2.54mm
Pitch - Termination Interface	1.90mm, 2.54mm
Polarized to Mating Part	Yes
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-20°C to +85°C
Termination Interface: Style	Solder or Weld
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	3.0A
Shielded	Yes
Voltage - Maximum	40V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-88741-008, SD-88741-8700

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(a),6(c)

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

88744 Series

Mates With

74320 Receptacles

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION