


**MMT FEMALE 20 CM
CABLE 2.6/50 S-BR**

R284.008.004

SERIES

MMT

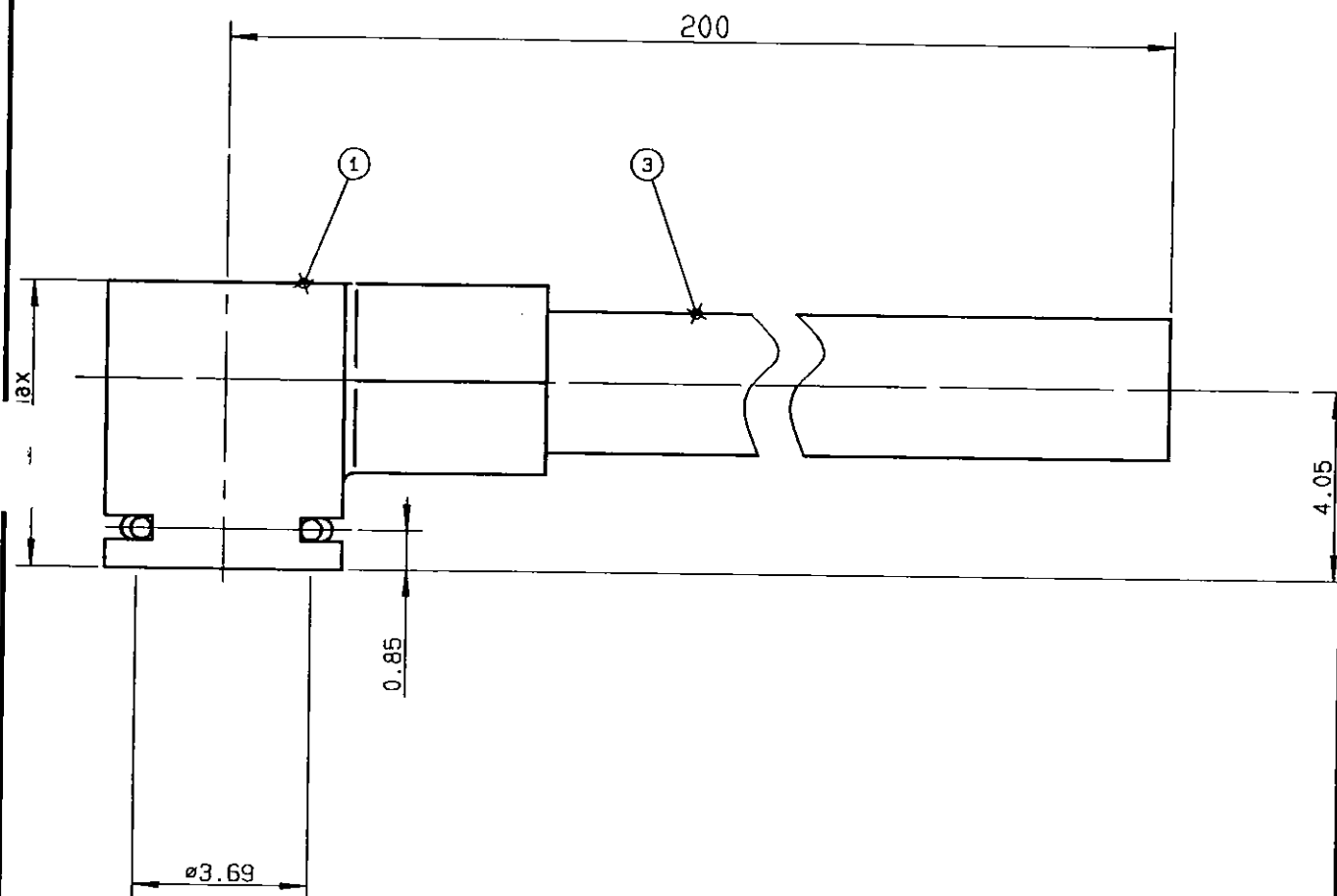

1 Connector A : R210.157.000
 2 Connector B :
 3 Cable : C291.150.000
 Type : CAB HF 2.6/50 RG 174 BLACK

NOMINAL IMPEDANCE 50 Ω
 FREQUENCY RANGE 0-8 GHz
 TEMPERATURE RATING -55/+100 °C
 V.S.W.R 1.10 + .05 x F(GHz)Maxi
 RF INSERTION LOSS 0.20 $\sqrt{F}$ (GHz) dB Maxi
 VOLTAGE RATING 170 Veff Maxi
 DIELECTRIC WITHSTANDING VOLTAGE 500 Veff Mini
 INSULATION RESISTANCE 5000 M Ω Mini

WEIGHT gr
 CABLE RETENTION 40 N Mini

OTHERS CHARACTERISTICS

SPECIFICATION

ISSUE

CREATION DATE

FILE PART-NUMBER

9722A02

10-OCT-96



RADIALL®