

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192040014](#)
Status: **Active**
Overview: [Splices](#)
Description: InsulKrimp™ 3 Way Splice for 14-16 AWG Wire

Documents:
[3D Model](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family [Splices](#)
Series [19204](#)
Comments 3 Way Connector
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Splices](#)
Product Name 3 Way, InsulKrimp™
UPC 800753051645


Physical
Barrel Type Closed
Color - Resin Blue
Insulation PVC
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin PVC
Net Weight 3.311/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Temperature Range - Operating -40°C to +105°C
Wire Insulation Diameter 4.45mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Electrical
Voltage - Maximum 600V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number B-2YCX

Reference - Drawing Numbers
Product Specification PS-19902-009-001, PS-19902-011-001,
PS-19902-013-001
Sales Drawing SD-19204-001

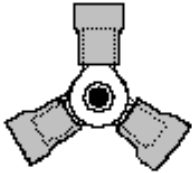

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/01/2017 (12 January 2017) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV RoHS Phthalates	Green Image Not Relevant Not Contained
---	---	--

Search Parts in this Series
[19204 Series](#)