

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192040017](#)
Status: **Active**
Overview: [Splices](#)
Description: Avikrimp™ 4 Way Splice for 14-16 AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Splices
Series [19204](#)
Comments 4 Way Connector
Crimp Quality Equipment Yes
Mil-Spec N/A
MolexKits Yes
Overview [Splices](#)
Product Name 4 Way, Avikrimp™
UPC 800753051669

Physical
Barrel Type Closed
Color - Resin Natural
Insulation Nylon (PA)
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 5.372/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Temperature Range - Operating -55°C to +105°C
Wire Insulation Diameter 4.32mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Electrical
Voltage - Maximum 600V

Material Info
Engineering Number B-5XC

Reference - Drawing Numbers
Product Specification PS-19902-009-001, PS-19902-011-001,
PS-19902-013-001
Sales Drawing SD-19204-002

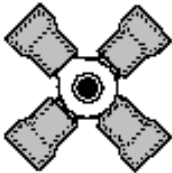

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
--	-------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[19204](#) Series