

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050375023

Status:

Active

Overview:

SPOX™ Wire-to-Board Connectors

Description:

2.50mm Pitch SPOX™ Wire-to-Board Crimp Housing, Friction Lock, 2 Circuits

Documents:

3D Model

Packaging Specification SPK-5264-001-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-5264-001-001 (PDF)

Agency Certification

UL

E29179

General

Product Family

Crimp Housings

Series

5264

Application

Signal, Wire-to-Board

MolexKits

Yes

Overview

SPOX™ Wire-to-Board Connectors

Product Name

SPOX™

UPC

800753578340

Physical

Circuits (maximum)

2

Flammability

94V-0

Gender

Female

Glow-Wire Compliant

No

Lock to Mating Part

Yes

Net Weight

119.300/mg

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

2.50mm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

-40°C to +105°C

Material Info

Engineering Number

5264-02

Reference - Drawing Numbers

Packaging Specification


SPK-5264-001-001

Product Specification

PS-5264-001-001

Sales Drawing

SD-5264-N

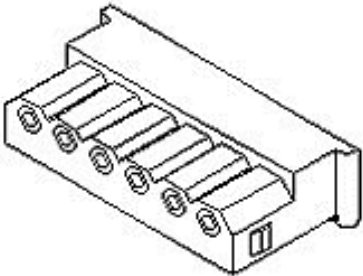

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per  
-ED/01/2017 (12  
January 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product  
environmental compliance?

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any  
non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

5264 Series

Mates With

5267 Vertical Shrouded PCB Header <br>  
5268 Right Angle Shrouded PCB Header

Use With

5263 2.50mm Pitch SPOX™ Crimp Terminal

This document was generated on 02/15/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION