

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395443003

Status:


Active

Overview:

Eurostyle™ Terminal Blocks

Description:

5.08mm Pitch Eurostyle™ Vertical Fixed Mount PCB Terminal Block, 3 Circuits

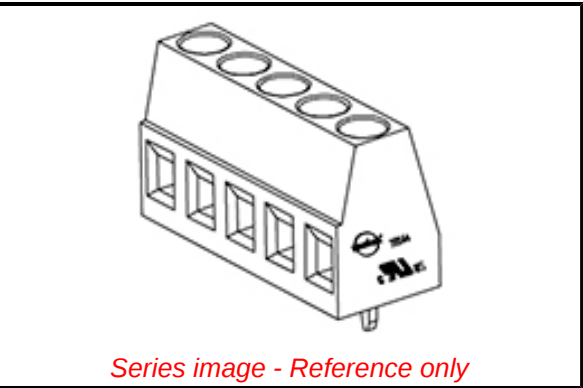

Documents:	
3D Model	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	
Agency Certification	
UL	E48521
General	
Product Family	Terminal Blocks
Series	39544
Application	N/A
Component Type	One Piece
MolexKits	Yes
Overview	Eurostyle™ Terminal Blocks
Product Name	ESE, Eurostyle™ Fixed Mount
Type	Euro Block
UPC	822350546997
Physical	
Circuits (Loaded)	3
Entry Angle	Horizontal
Lock to Mating Part	None
Net Weight	4.280/g
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.00mm
PCB Thickness - Recommended	2.00mm
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	N/A
Stackable	No
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	12, 14, 16, 18, 20, 22
Wire Size mm²	0.33-3.31
Electrical	
Current - Maximum per Contact	15.0A
Voltage - Maximum	300V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	005
Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	135
Process Temperature max. C	260
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-39544-001

EU ELV
Not Relevant

EU RoHS
Compliant with Exemption 6(c)
REACH SVHC
Not Contained Per
-ED/01/2017 (12
January 2017)
Halogen-Free
Status
Low-Halogen
Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China RoHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

39544 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION