

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


0510060400

Status:

Active

Description:

2.00mm Pitch Wire-to-Wire Plug Housing, 4 Circuits

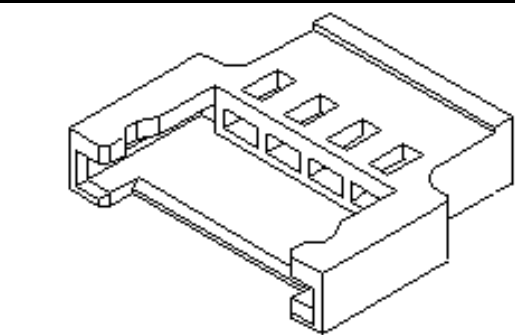

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

Product Specification PS-51005-001-001 (PDF)

Packaging Specification SPK-51006-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	51006
Application	Signal, Wire-to-Wire
MolexKits	Yes
Product Name	N/A
UPC	800753719415
Physical	
Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-0
Gender	Male
Glow-Wire Compliant	No
Lock to Mating Part	None
Material - Resin	Polyester
Net Weight	180.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C
Electrical	
Current - Maximum per Contact	2.0A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-51006-001-001
Product Specification	PS-51005-001-001
Sales Drawing	SD-51006-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Compliant

REACH SVHC

Not Contained Per -ED/01/2017 (12 January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

51006 Series

Mates With

51005 Female Housing

Use With

50012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION