

Key Features

- Silent PSU with Temperature Control Fan
- ATX 12V Compliant for all kinds of CPU and mainboard
- MTBF 50,000 Hours @ 25 degrees C
- 2 x SATA Connectors
- 4 x 4-Pin Molex Connectors

PSU Specifications


AC INPUT: 230 VAC 4A 50-60Hz					
DC	+3.3V	+5V	+12V1	-12V	+5VSB
Output	18A	20A	21A	0.3A	2A
Max	400W				

Connectors



20+4 Pin Main Connectors:

1

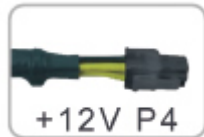


4-Pin 12V Connectors:

1




SATA Connectors:

2

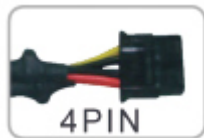

4-Pin Molex Connectors:

4

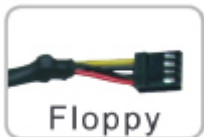

Floppy Drive Connectors:

1

Detailed Specifications

Dimensions:	125mm x 65mm x 100mm (W x H x D)
Input Voltage:	230 VAC
Input Current:	4A
Input Frequency Range:	50-60Hz
PFC:	Yes - Power Factor Control
Power Good Signal:	150-450 ms
Hold Up Time:	1MS-40MS
Efficiency:	75%
MTBF:	100,000 Hours
Protection:	OVP / UVP/ OPP
Power:	400W
Operation Temperature:	45°C
Safety:	CE / ROHS

Cooling: 8cm Fan

Noise: < 17 dBA

General Specifications

Manufacturer Part Number: M-400U

EAN Number: 5055492411051

Has Mains Plug: No

Colour: Grey

What's In The Box: PSU

Unit (Product) Dimensions (mm): 126mm x 64mm x 101mm (W x H x D)

Packaging Dimensions (mm): 163mm x 76mm x 141mm (W x H x D)

Net Weight (KGs): 0.7 KGs

Gross Weight (KGs): 0.8 KGs