

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0351500610](#)
Status: **Active**
Overview: [VersaBlade™ Wire-to-Wire Connector System](#)
Description: Wire-to-Wire VersaBlade™ Hybrid Plug Housing, with Mounting Ears, 6 Circuits, Polyester UL94V-0, Natural

Documents:

[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-35150-003-001 \(PDF\)](#)
[Packaging Specification PK-35150-005-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series [35150](#)
Application Power, Wire-to-Wire
Comments Polarized to Mating Part, Positive Lock
Overview [VersaBlade™ Wire-to-Wire Connector System](#)
Product Name VersaBlade™
UPC 800754375511


Physical

Circuits (maximum) 6
Color - Resin Natural
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Keying to Mating Part None
Lock to Mating Part Yes
Material - Resin Polyester
Net Weight 6.133/g
Number of Rows 2
Packaging Type Bag
Panel Mount Yes
Pitch - Mating Interface 7.30mm
Pitch - Termination Interface 7.30mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40°C to +120°C

Material Info

Reference - Drawing Numbers

Packaging Specification PK-35150-005-001
Product Specification PS-35150-003-001
Sales Drawing SD-35150-061*

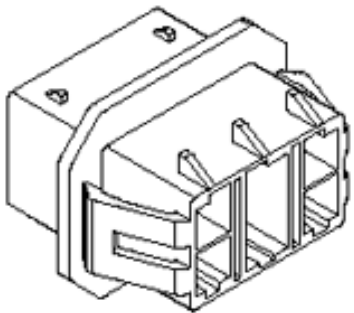

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series

[35150](#) Series

Mates With

[35151-0610](#) Receptacle Housing,
[35151-0614](#) Receptacle Housing

Use With

VersaBlade™ Crimp Terminals, [35745](#) ,
[35746](#) , [35747](#)