


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0510050200
Status: Active
Description: 2.00mm Pitch Wire-to-Wire Receptacle Housing, 2 Circuits

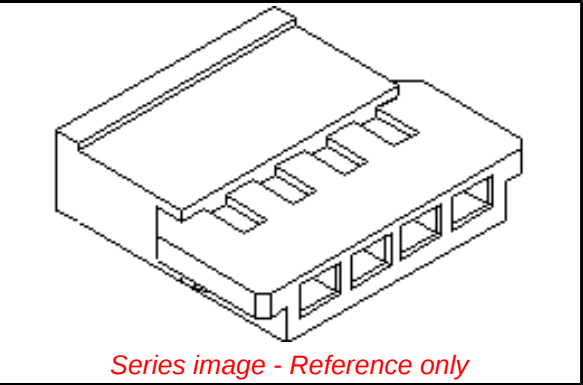

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-51005-001-001 \(PDF\)](#)
[Packaging Specification SPK-51005-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series 51005
Application Signal, Wire-to-Wire
MolexKits Yes
Product Name N/A
UPC 800753576056

Physical
Circuits (maximum) 2
Color - Resin Natural
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Lock to Mating Part None
Material - Resin Polyester
Net Weight 78.140/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.00mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Electrical
Current - Maximum per Contact 2.0A

Material Info

Reference - Drawing Numbers
Packaging Specification SPK-51005-001-001
Product Specification PS-51005-001-001
Sales Drawing SD-51005-001

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/01/2017 (12
January 2017)
Halogen-Free
Status
Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[51005](#) Series

Mates With
[51006](#) Male Housing

Use With
[50013](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION