

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0430310001](#)
Status: **Active**
Overview: [Micro-Fit 3.0™ Connectors](#)
Description: Micro-Fit 3.0™ Crimp Terminal, Male, with Tin (Sn) Plated Phosphor Bronze Contact, 20-24 AWG, Reel

Documents:

- [Drawing \(PDF\)](#)
[Product Specification PS-43045 \(PDF\)](#)
[Product Specification TS-46235-001-001 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)
[Product Literature \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	43031
Application	Power
Crimp Quality Equipment	Yes
Overview	Micro-Fit 3.0™ Connectors
Packaging Alternative	43031-0007 (Loose)
Product Literature Order No	987650-5984
Product Name	Micro-Fit 3.0™
UPC	800753683679

Physical

Gender	Male
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.061/g
Packaging Type	Reel
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.85mm max.
Wire Size AWG	20, 22, 24
Wire Size mm²	N/A


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Product Specification	PS-43045, TS-46235-001-001
Sales Drawing	SD-43031-****

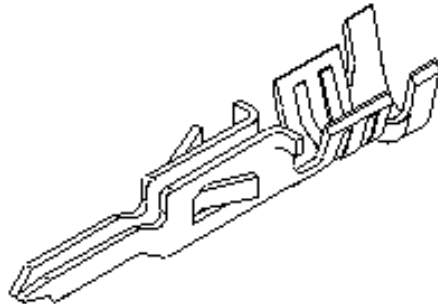

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series

[43031](#) Series

Mates With

[43030](#) Micro-Fit 3.0™ Female Crimp
Terminals

Use With

[43020](#) , [43640](#) Micro-Fit 3.0™ Plug
Housings, [44300](#) Micro-Fit BMI™ Panel
Mount Plug Housings

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION