

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0510470500

Status:


Active

Overview:

PicoBlade™ Connector System

Description:

1.25mm Pitch PicoBlade™ Wire-to-Wire Plug Housing, 5 Circuits

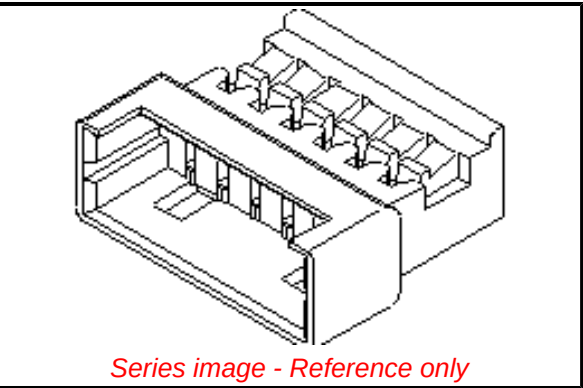

Documents:	
3D Model	Product Specification PS-51021-009-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	51047
Application	Signal, Wire-to-Wire
Current Derating Order No	987651-3691
Overview	PicoBlade™ Connector System
Product Name	PicoBlade™
UPC	800753756182
Physical	
Circuits (maximum)	5
Color - Resin	Natural
Gender	Male
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	96.800/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Stackable	No
Temperature Range - Operating	-40°C to +85°C
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-51021-009-001
Sales Drawing	SD-51047-**00

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -ED/01/2017 (12 January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

51047 Series

Mates With

51021 Housing

Use With

50125 Crimp Terminal, 50133 Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION