

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0834219041

Status:


Active

Overview:

Commercial Micro-D High-Density Connectors

Description:

Commercial Micro-D, CMD-to-D-Sub, 9 Circuits, Female - Female, 1.83m Length

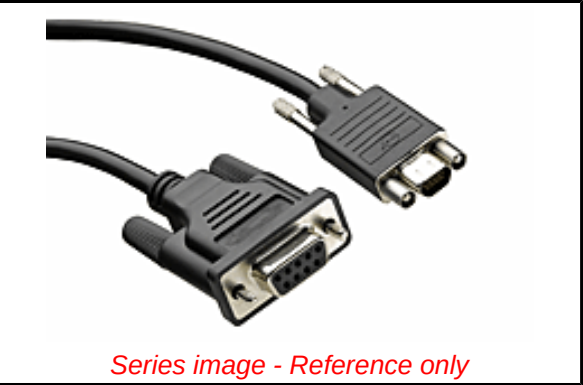

Documents:	
Drawing (PDF)	Packaging Specification PK-83422-001 (PDF)
Product Specification PS-83421-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	83421
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Commercial Micro-D-to-D-Sub
Overview	Commercial Micro-D High-Density Connectors
Product Name	Commercial Micro-D, D-Sub
UPC	800756424668
Physical	
Cable Length	1.83m
Circuits (Loaded)	9
Gender	Female-Female
Lock to Mating Part	None
Material - Plating Termination	Tin
Net Weight	0.569/g
Packaging Type	Bag
Plating min - Mating	0.127µm
Plating min - Termination	1.270µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	PVC
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-83422-001
Product Specification	PS-83421-001-001
Sales Drawing	SD-83421-020

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -ED/01/2017 (12 January 2017)	
Halogen-Free	
Status	
Low-Halogen	
Need more information on product environmental compliance?	
Email productcompliance@molex.com	
Please visit the Contact Us section for any non-product compliance questions.	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

83421 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION