

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0003122026
Status: Active
Description: 3.18mm Diameter, HCS125, Pin and Socket Plug Housing, Single Row, without Panel Mount Ears, 2 Circuits, Natural (Translucent)

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PSX-42179-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR19980
UL E29179
General
Product Family Crimp Housings
Series 42179
Application Power, Wire-to-Wire
MolexKits Yes
Product Name HCS-125
UPC 800753614925

Physical
Circuits (maximum) 2
Color - Resin Natural
Flammability 94V-2
Gender Dual
Glow-Wire Compliant No
Lock to Mating Part Yes
Material - Resin Nylon
Net Weight 2.618/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 8.38mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40°C to +105°C

Electrical
Current - Maximum per Contact 20.0A

Material Info
Engineering Number 42179-2P1

Reference - Drawing Numbers
Product Specification PSX-42179-001
Sales Drawing SD-42179-2*

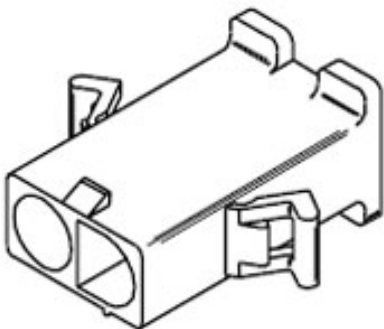

Series image - Reference only

EU ELV
Not Relevant
EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/01/2017 (12
January 2017)
Halogen-Free
Status
Low-Halogen
Need more information on product environmental compliance?
Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.
China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[42179](#) Series

Mates With
[03-12-1026](#)

Use With
[1900](#) Male Crimp Terminals, [1901](#) , [2046](#) ,
[2047](#) , [42546](#) , [42547](#) , [42554](#) , [42555](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION