

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0192040026
Status: Active
Overview: Splices
Description: InsulKrimp™ 3 Way Splice for 10-12 AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Splices
Series 19204
Comments 3 Way Connector
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Splices
Product Name 3 Way, InsulKrimp™
UPC 800753051812


Physical
Barrel Type Closed
Color - Resin Natural
Insulation PVC
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin PVC
Net Weight 6.002/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Temperature Range - Operating -40°C to +105°C
Wire Insulation Diameter 6.35mm max.
Wire Size AWG 10, 12
Wire Size mm² 3.30-5.00

Electrical
Voltage - Maximum 600V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number C-2YCX

Reference - Drawing Numbers
Product Specification PS-19902-009-001, PS-19902-011-001,
PS-19902-013-001
Sales Drawing SD-19204-001

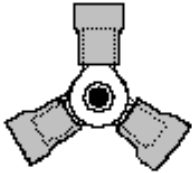

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/01/2017 (12
January 2017)
Halogen-Free
Status
Not Low-Halogen
**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19204 Series](#)