

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0192160004
Status: Active
Overview: Splices
Description: Multi-Lock Connector for 14-18 AWG Wire

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E32244

General
Product Family Splices
Series 19216
Comments Width 13.97mm (.550")
Crimp Quality Equipment Yes
Mil-Spec N/A
MolexKits Yes
Overview Splices
Product Name Multi-Lock
UPC 800753025943


Physical
Barrel Type Closed
Color - Resin White
Flammability 94V-0
Insulation Polypropylene
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 1.334/g
Packaging Type Bag
Wire Insulation Diameter 3.30mm & 3.56mm
Wire Size AWG 14, 16, 18
Wire Size mm² 0.96-2.60

Electrical
Voltage - Maximum 600V

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number ML-1814

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing SD-19216-003

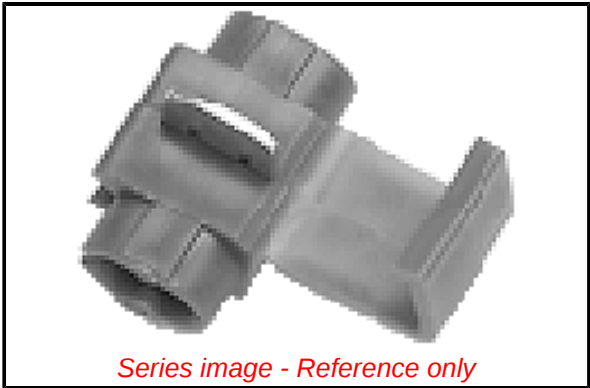

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/01/2017 (12
January 2017)
Halogen-Free
Status
Low-Halogen
Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19216](#) Series