
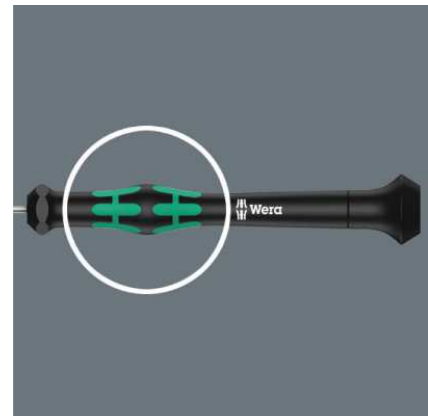


2035 Screwdriver for slotted screws for electronic applications,
0.40 x 2.0 x 60 mm
s/driver for slotted screws

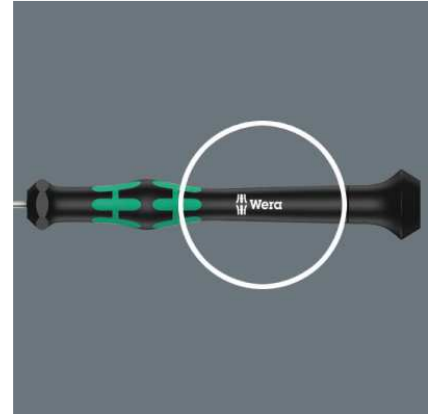

| | | | |
|-------------|---------------|---------------------|--------------|
| EAN | 4013288031891 | Dimension: | 157x13x13 mm |
| Code: | 05118006001 | Weight: | 11,78 g |
| Article-No. | | Country of origin: | CZ |
| | | Customs tariff no.: | 82054000 |

- Kraftform Micro screwdriver for slotted screws
- Multi-component Kraftform Micro handle for fast and ergonomic screwdriving
- Anti-roll feature and swivel cap for rapid twisting
- The Wera Black Point tip offers an exact fit and optimum corrosion protection
- E.g. for electricians, opticians, precision mechanics, jewellers or IT hardware fitters

High quality Wera Micro screwdriver for precision mechanical jobs. Rapid twisting results from fixing the hand on the head and using the fast-turning zone just below. This makes time-consuming grip adjustments unnecessary. Power zones with integrated soft sections ensure the transfer of high loosening and tightening torque; a precision zone for the right rotation angle during fine adjustment work. The Black Point tip offers optimised corrosion protection and an exact fit.