


Joker Double Open-Ended Wrench, 17 und 19 x 235 mm

Joker Double Open-Ended Wrench

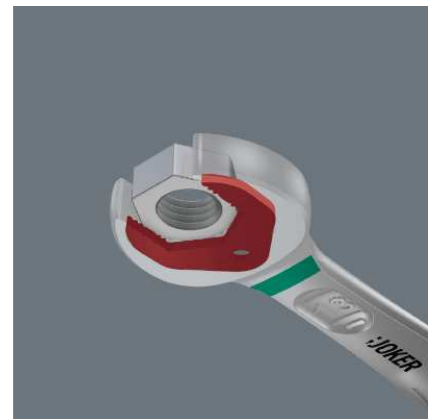

EAN	4013288173027	Dimension:	292x55x15 mm
Code:	05003765001	Weight:	254 g
Article-No.		Country of origin:	CZ
		Customs tariff no.:	82041100

- Practical holding function thanks to the metal plate in the jaw
- Limit stop prevents any slipping
- The double-hex geometry reduces the risk of slipping
- Return angle of only 30°
- Take it easy Tool Finder: colour coding according to profile and size

High quality, metric double open-end wrench by Wera: everything that a wrench has to be able to do. And a whole lot more. Faster, better, stylish. Yes, a real Joker. The new generation of combination ratchet wrenches for hexagonal head bolts and nuts. It has a holding function, thanks to the metal plate in the jaw, which reduces the risk of dropping nuts and bolts. The replaceable metal plate in the jaw secures nuts and bolts with its extra hard teeth and reduces the danger of slipping. The integrated limit stop prevents any slipping downwards around the bolt head and allows higher torque to be applied. The double-hex geometry makes for a positive connection with nuts or bolts and reduces the risk of slipping. A return angle of only 30° prevents any time consuming flipping of the wrench during fastening jobs. The specially forged geometry ensures high torque transfer and great strength. Manufactured out of high performance chrome-molybdenum steel with nickel-chrome coating for high corrosion protection. "Take it easy" Tool Finder with colour coding according to sizes.