




GREENLEE.
A Textron Company

MADE FOR THE TRADE!™

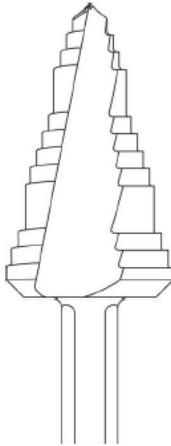

BIT, K/S STEP #8 (PKGD)

Kwik Stepper® Step Bits

MPN 30008

Cat No: 50300083

UPC No: 783310300083

Description

- Unique split-tip design penetrates through steel faster
- Resists walking or skidding, even on round surfaces
- Balanced, double-flute construction requires less pressure, does the work for you
- Designed and manufactured in USA.

Specifications

- Capacity : Cut Up Through 3/8 IN (9.500 MM) Mild Steel, Copper, Brass, Aluminum, Wood, Plastic and Laminates
- Hole Size : 1/2 IN (12.700 MM), 7/8 IN (22.200 MM), 1-1/8 IN (28.600 MM)
- Maximum Material Thickness : 10 GA (3.500 MM)
- Minimum Chuck Size : 3/8 IN (9.500 MM)
- Overall Length : 2-15/16 IN (74.600 MM)
- Sub Brand : Kwik Stepper® #174
- Type : Multi Hole