


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0192040004](#)
Status: **Active**
Overview: [Splices](#)
Description: InsulKrimp™ 3 Way Splice for 18-22 AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)
[Product Specification PS-19902-013-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Splices
Series	19204
Comments	3 Way Connector
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Splices
Product Name	3 Way, InsulKrimp™
UPC	800753051584
Physical	
Barrel Type	Closed
Color - Resin	Red
Insulation	PVC
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	2.324/g
Packaging Type	Bag
Temperature Range - Operating	-40°C to +105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.68mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	0.35-0.80
Electrical	
Voltage - Maximum	600V
Material Info	
Engineering Number	A-2YCX
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19204-001

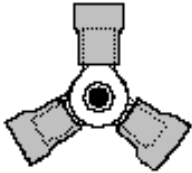

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/01/2017 (12 January 2017) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[19204 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION