

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


0901230124

Status:

Active

Description:

2.54mm Pitch C-Grid III™ Modular Crimp Housing Single Row, 2 Polarizing Buttons, 24 Circuits

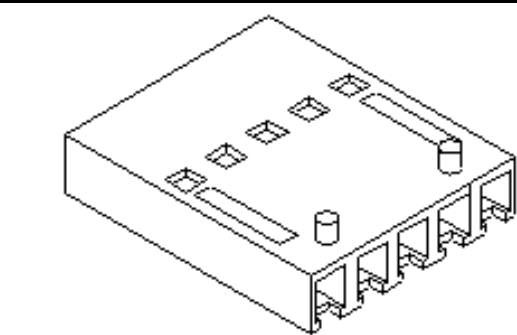

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

Packaging Specification PK-90123-0001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E29179
General		
Product Family		Crimp Housings
Series		90123
Application		Signal, Wire-to-Board
Comments		2 Polarizing Buttons
Product Name		C-Grid III™
UPC		800753705241
Physical		
Circuits (maximum)		24
Color - Resin		Black
Flammability		94V-1
Gender		Receptacle
Glow-Wire Compliant		No
Material - Resin		PPO
Net Weight		1.385/g
Number of Rows		1
Packaging Type		Bag
Panel Mount		No
Pitch - Mating Interface		2.54mm
Stackable		Yes
Temperature Range - Operating		-55°C to +105°C
Material Info		
Reference - Drawing Numbers		
Packaging Specification		PK-90123-0001
Sales Drawing		SD-90123

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -ED/01/2017 (12 January 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

90123 Series

Mates With

C-Grid III™ Header 90120 , 90121 , C-Grid III™ Header 90136

Use With

C-Grid III™ Crimp Terminal 90119

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION