

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0022552503

Status:

Active

Overview:

SL™ Modular Connectors

Description:

2.54mm Pitch SL™ Crimp Housing, Dual Row, Version C, Back Ribs, 50 Circuits

Documents:

3D Model

Drawing (PDF)

Product Specification PS-70058-001 (PDF)

Product Specification PS-70400-001 (PDF)

Product Specification TS-70058-001-001 (PDF)

Product Specification TS-70541-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Application

Comments

Overview

Product Name

UPC

Crimp Housings

70450

Signal, Wire-to-Board

Version C

SL™ Modular Connectors

SL™

800753778757

Physical

Breakaway

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Compliant

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Stackable

Temperature Range - Operating

No

50

Black

94V-0

Receptacle

No

Polyester

4.282/g

2

Bag

No

2.54mm

Yes

-40°C to +105°C

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Engineering Number

70450-0123


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-70058-001, PS-70400-001, TS-70058-001-001, TS-70541-001-001

SD-70450-0100-0125

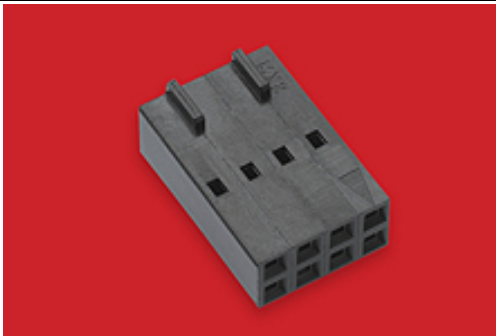

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per

-ED/01/2017 (12

January 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

70450 Series

Mates With

2.54mm Pitch C-Grid® Header [70229](#) ,

[70280](#) , [70246](#) , [70247](#)

Use With

[70058](#) , [71851](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION