

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0395443002

Status:


Active

Overview:

Eurostyle™ Terminal Blocks

Description:

5.08mm Pitch Eurostyle™ Vertical Fixed Mount PCB Terminal Block, 2 Circuits

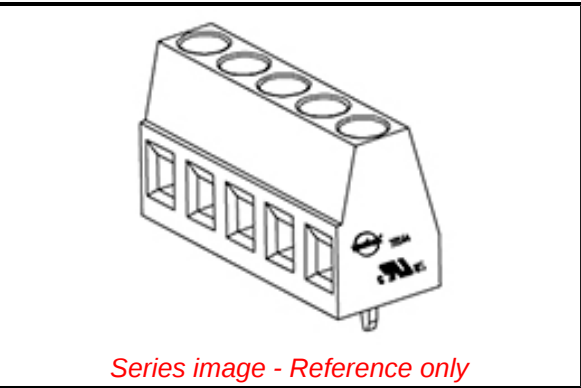

Documents:

3D Model

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E48521

General

Product Family

Series

Application

Component Type

MolexKits

Overview

Product Name

Type

UPC

Terminal Blocks

39544

N/A

One Piece

Yes

Eurostyle™ Terminal Blocks

ESE, Eurostyle™ Fixed Mount

Euro Block

822350546973

Physical

Circuits (Loaded)

Entry Angle

Lock to Mating Part

Net Weight

Number of Rows

Orientation

PC Tail Length

PCB Thickness - Recommended

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Stackable

Temperature Range - Operating

Wire Size AWG

Wire Size mm²

2

Horizontal

None

2.820/g

1

Vertical

3.00mm

2.00mm

No

5.08mm

5.08mm

N/A

No

-40°C to +105°C

12, 14, 16, 18, 20, 22

0.33-3.31

Electrical

Current - Maximum per Contact

Voltage - Maximum

15.0A

300V

Solder Process Data

Duration at Max. Process Temperature (seconds)

Lead-freeProcess Capability

Max. Cycles at Max. Process Temperature

Process Temperature max. C

005

WAVE

135

260

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-39544-001

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per -ED/01/2017 (12 January 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

39544 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION