

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0923151025
Status: Active
Overview: Picoflex® Ribbon-Cable Connectors
Description: Picoflex® PF-50 IDT-to-IDT, 10 Circuits, 0.25m Length

Documents:
[3D Model](#) [Product Specification PS-99020-0011 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Cable Assemblies
Series 92315
Application Tooling Part Link 62100-6000
Application Tooling Part Link 62100-6010
Assembly Configuration Dual Ended Connectors
Connector to Connector Picoflex® IDT-to-IDT
Overview Picoflex® Ribbon-Cable Connectors
Product Name Picoflex®
UPC 800754779692

Physical
Cable Length 0.25m
Circuits (Loaded) 10
Color - Resin Natural
Gender Female-Female
Lock to Mating Part None
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Polyester
Net Weight 5.490/g
Packaging Type Bag
Pitch - Mating Interface 1.27mm
Plating min - Mating 2.032µm
Plating min - Termination 2.032µm
Single Ended No
Termination Interface: Style IDT or Pierce
Waterproof / Dustproof No
Wire Insulation Diameter N/A
Wire Size AWG 28
Wire/Cable Type PVC, Ribbon Cable

Electrical
Current - Maximum per Contact 1.2A
Shielded No
Voltage - Maximum 250V

Material Info

Reference - Drawing Numbers
Product Specification PS-99020-0011
Sales Drawing SD-92315-001

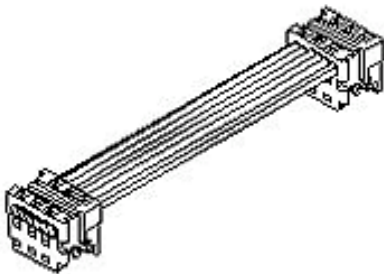

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/01/2017 (12 January 2017) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
---	--

Search Parts in this Series
[92315](#) Series

Mates With
Picoflex® PF-50 Header [90325](#) , [90800](#) ,
[90779](#) , [90715](#) , [90814](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION