


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0901560144
Status: Active
Overview: C-Grid III™
Description: 2.54mm Pitch C-Grid III™ Crimp Housing Single Row, 4 Circuits

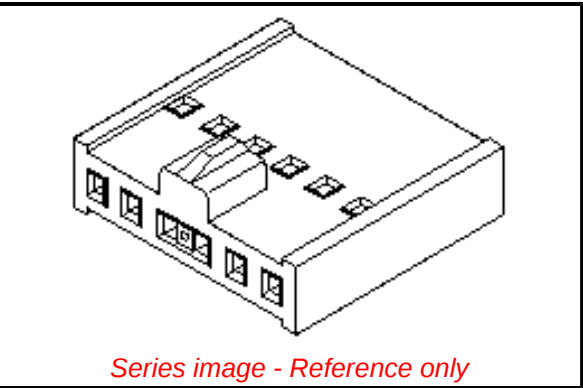

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Packaging Specification PK-90156-0001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	90156
Application	Signal, Wire-to-Board
MolexKits	Yes
Overview	C-Grid III™
Product Name	C-Grid III™
UPC	800753756717
Physical	
Breakaway	No
Circuits (maximum)	4
Color - Resin	Black
Gender	Receptacle
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	PPO
Net Weight	0.366/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Temperature Range - Operating	-55°C to +105°C
Electrical	
Current - Maximum per Contact	3.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-90156-0001
Sales Drawing	SDA-90156

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/01/2017 (12
January 2017)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

90156 Series

Mates With

90120 , 90121, 90136

Use With

90119

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION