


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0901420030
Status: Active
Overview: C-Grid III™
Description: 2.54mm Pitch C-Grid III™ Crimp Housing Dual Row, 30 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-99020-0001-001 \(PDF\)](#)
[Packaging Specification PK-90142-0001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	90142
Application	Signal, Wire-to-Board
Overview	C-Grid III™
Product Name	C-Grid III™
UPC	800753657298
Physical	
Breakaway	No
Circuits (maximum)	30
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PPO
Net Weight	2.000/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Pitch - Termination Interface	2.54mm
Polarized to Mating Part	Yes
Ports	0
Stackable	No
Temperature Range - Operating	-55°C to +105°C
Electrical	
Current - Maximum per Contact	3.0A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-90142-0001
Product Specification	PS-99020-0001-001
Sales Drawing	SD-90142

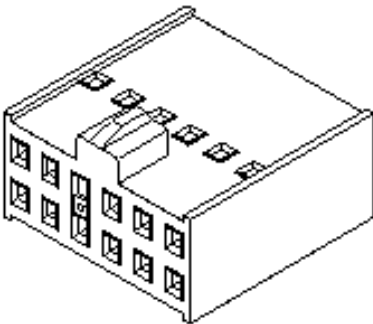

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/01/2017 (12 January 2017) Halogen-Free Status Low-Halogen	China RoHS
--	-------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[90142](#) Series

Mates With
C-Grid III™ Header, Dual Row [90122](#) ,
[90130](#) , [90131](#)

Use With
C-Grid III™ Crimp Terminal [90119](#)