

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [0903270308](#)
Status: **Active**
Overview: [Picoflex® Ribbon-Cable Connectors](#)
Description: [Picoflex® PF-50, Low Profile, IDT Receptacle, 8 Circuits, White, Tin \(Sn\) Plated, Bag](#)

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-99020-0011 \(PDF\)](#)
[Packaging Specification PK-90327-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification		
CSA		LR19980
UL		E29179
General		
Product Family		Ribbon Cable / Wire Trap Connectors
Series		90327
Comments		Low Profile
Component Type		Housing
Glow-Wire Compliant		No
MolexKits		Yes
Overview		Picoflex® Ribbon-Cable Connectors
Product Name		Picoflex®
UPC		800753538122

Physical		
Circuits (Loaded)		8
Circuits (maximum)		8
Color - Resin		White
Durability (mating cycles max)		30
Entry Angle		Vertical
Flammability		94V-0
Lock to Mating Part		Yes
Material - Metal		Phosphor Bronze
Material - Plating Mating		Tin
Material - Plating Termination		Tin
Material - Resin		Polyester
Net Weight		0.510/g
Number of Rows		2
PCB Locator		No
PCB Retention		None
Packaging Type		Bag
Pitch - Mating Interface		1.27mm
Pitch - Termination Interface		1.27mm
Polarized to Mating Part		Yes
Polarized to PCB		No
Shrouded		Fully
Stackable		No
Surface Mount Compatible (SMC)		N/A
Temperature Range - Operating		-40°C to +105°C
Termination Interface: Style		IDT or Pierce
Wire Insulation Diameter		1.00mm max.
Wire Size AWG		26, 28
Wire/Cable Type		Ribbon Cable

Electrical		
Current - Maximum per Contact		1.2A

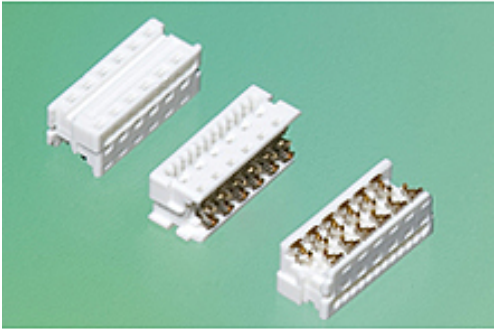

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/01/2017 (12 January 2017) Halogen-Free Status Not Low-Halogen	China RoHS
--	-------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[90327](#) Series

Mates With
Low Profile Vertical [90325](#) , Low Profile Right Angle [90800](#) , [90715](#) , [90814](#) , [90779](#)
Vertical, [91714](#) 1.27mm Pitch Picoflex® PF-50 Header

Voltage - Maximum	250V
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-90327-001-001
Product Specification	PS-99020-0011
Sales Drawing	SDA-90327

This document was generated on 05/25/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION