

Protective covers - HC-B06-BC-HI-PLBK - 1407692

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

HEAVYCON EVO hinged protective cover, size B6, for EVO plastic supporting base element, IP65, PA



Product Description

Plastic protective cover for HC-EVO... consisting of plastic protective cover, flange, self-tapping screw for plastic



Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 776776
GTIN	4046356776776
Weight per Piece (excluding packing)	32.100 g
Custom tariff number	85389099
Country of origin	Poland

Technical data

Ambient conditions

Degree of protection	IP65
	IP66
Ambient temperature (operation)	-40 °C ... 100 °C

General

Size	B6
Material	PA
Flammability rating according to UL 94	V0
Assembly instructions	For HC-EVO.....PLBK

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Environmental Product Compliance

Protective covers - HC-B06-BC-HI-PLBK - 1407692


Technical data

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

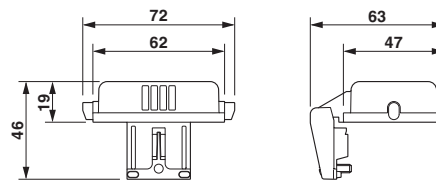

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27141210
eCl@ss 4.1	27141210
eCl@ss 5.0	27149110
eCl@ss 5.1	27149110
eCl@ss 6.0	27261210
eCl@ss 7.0	27440208
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

ETIM

ETIM 2.0	EC000241
ETIM 3.0	EC002040
ETIM 4.0	EC002314
ETIM 5.0	EC002314
ETIM 6.0	EC002314

UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121421

Approvals

Approvals

Protective covers - HC-B06-BC-HI-PLBK - 1407692

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	---	---------------------
