

Screwdriver - SZK PH0 VDE - 1205147

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Screwdriver, PH crosshead, VDE insulated, size: PH 0 x 80 mm, 2-component grip, with non-slip grip

The figure shows the SZK PH2 version

Why buy this product

- VDE approval
- Screwdrivers for Phillips screws with Pozidriv and Phillips Recess screw head



Key Commercial Data

Packing unit	10 STK
GTIN	 4 017918 019150
GTIN	4017918019150
Weight per Piece (excluding packing)	33.510 g
Custom tariff number	82054000
Country of origin	Czech Republic

Technical data

Dimensions

Length (b)	161 mm
Width (a)	26 mm
Blade height	80 mm

General

Design	Phillips
Type	Straight
Material	Alloyed tool steel
Test standard	DIN/ISO 8764-1 PH IEC 60900:2004

Standards and Regulations

Screwdriver - SZK PH0 VDE - 1205147

Technical data

Standards and Regulations


Test standard	DIN/ISO 8764-1 PH IEC 60900:2004
---------------	----------------------------------

Drawings

Pictogram



Dimensional drawing

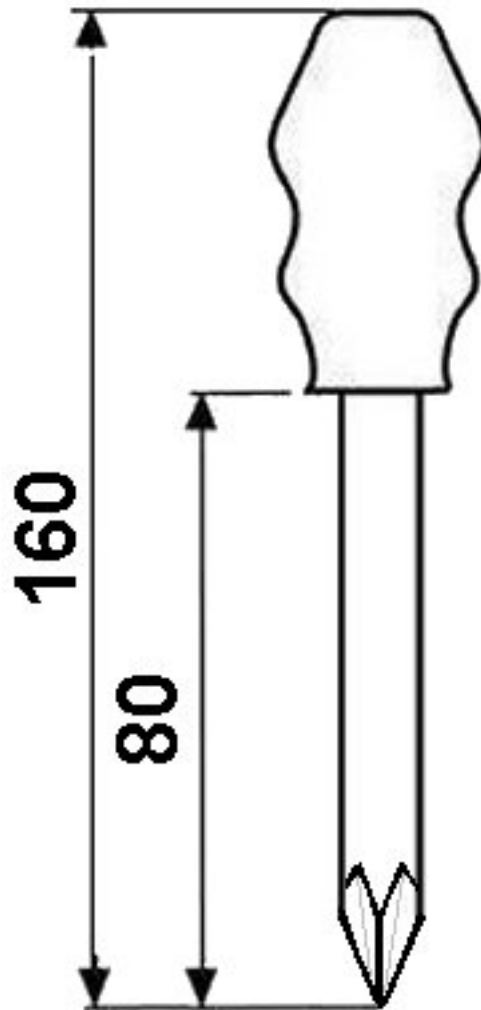

Classifications

eCl@ss

eCl@ss 4.0	21040401
eCl@ss 4.1	21040401
eCl@ss 5.0	21040401
eCl@ss 5.1	21040401

Screwdriver - SZK PH0 VDE - 1205147

Classifications

eCl@ss

eCl@ss 6.0	21040401
eCl@ss 7.0	21040409
eCl@ss 8.0	21040406
eCl@ss 9.0	21040406

ETIM

ETIM 2.0	EC000158
ETIM 3.0	EC000158
ETIM 4.0	EC000144
ETIM 5.0	EC000144
ETIM 6.0	EC000144

UNSPSC

UNSPSC 6.01	27111701
UNSPSC 7.0901	27111701
UNSPSC 11	27111701
UNSPSC 12.01	27111701
UNSPSC 13.2	27111701

Approvals

Approvals

Approvals

VDE Zeichengenehmigung / EAC

Ex Approvals

Approval details

VDE Zeichengenehmigung		http://www.vde.com/en/Institute/OnlineService/VDE-approved-products/Pages/Online-Search.aspx	086858
------------------------	--	---	--------

EAC		EAC-Zulassung
-----	--	---------------