


EMI Filters, Three Phase, FLLD3-MH, 530 VAC, 16 A, 220x45x70mm

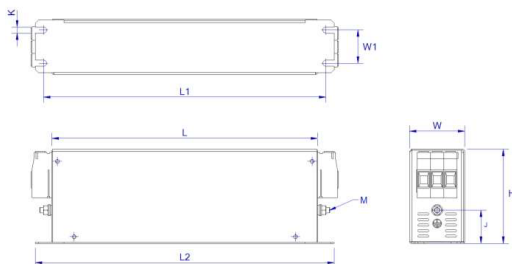

Dimensions

L	220mm NOM
W	45mm NOM
H	70mm NOM
L1	235mm NOM
L2	250mm NOM
W1	25mm NOM
J	22mm NOM
K	5.5mm NOM
M (Earth)	Threaded Studs M5

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	1
Weight:	700 g

General Information

Style:	Chassis Mount
Series:	FLLD3-MH
Description:	EMI Filter, Chassis Mount, Motor Drives
Features:	High Performance
RoHS:	Yes

Specifications

Voltage AC:	530/305 VAC
Rated Frequency:	50-60 Hz
Current:	16 A (50C)
Rated Temperature:	50C
Temperature Range:	-25/+100C
Climate Category:	25/100/21
Test Voltage DC (P to P):	2250 VDC
Test Voltage DC (P to E):	3000 VDC
Power Loss:	6 W (25C 50 Hz)
Leakage Current:	3.1 mA